

buy more,
save more5-9 pk/cs
save 10%10+ pk/cs
save 15%Mix and match packs or cases of
items from "red" tables to save!Bottles 03660-15 and 03662-10
shown in rack 03660-20

BOD Bottles and Bottle Racks

Clear Glass BOD Bottles come with glass stoppers and a white write-on marking space. Perfect for general BOD applications.

Black Plastisol-Coated BOD Bottles are perfect for light-sensitive BOD applications—coating blocks out light rays from 400 to 800 nm. Bottles include ground glass stopper, opaque cap, and foam insert.

Use a bottle rack for storing and transporting your BOD bottles. Racks are plastisol coated.

Catalog number	Description	Capacity	Qty/cs	Price/cs
R-03660-15	Clear, glass bottles	300 mL	24	
R-03662-10	Black, plastisol-coated glass bottles		20	

R-03660-09 Cap and insert for use with bottles 03660-15 and 03662-10. Pack of 50 /pk

R-03660-12 Rubber bottle leash holds stopper to bottle. Pack of 25 /pk

R-03660-20 BOD bottle rack holds twelve 300-mL bottles.....

R-03660-30 BOD bottle rack holds twenty-four 300-mL bottles



34523-14

34523-16

KIMAX® BOD Bottles

- Sample and incubate aqueous samples for BOD analysis

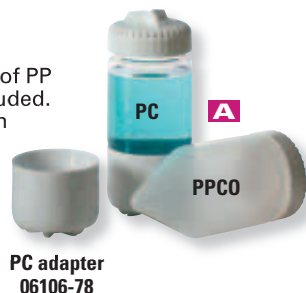
The flared mouth of these clear glass BOD bottles forms a water seal to prevent the sample from drawing air during incubation. Non-numbered bottle 34523-14 conforms to ASTM E438, Type I, Class B, borosilicate glass. For reference see Method 5210-B: 5-Day B.O.D. Test (Standard Methods for Examination of Water and Wastewater). Non-numbered bottle features conical stopper design to displace excess sample and the shoulder radius design to provide an interior shape that sweeps air out of the stopper opening.

Description	Capacity	Dimensions	Catalog number	Qty/cs	Price/cs
Non-numbered	300 mL	165 mm H x 69 mm dia	R-34523-14	24	
Large-volume	2000 mL	265 mm H x 135 mm W	R-34523-16	1	

NALGENE® Centrifuge Bottles

A 175-mL Bottles

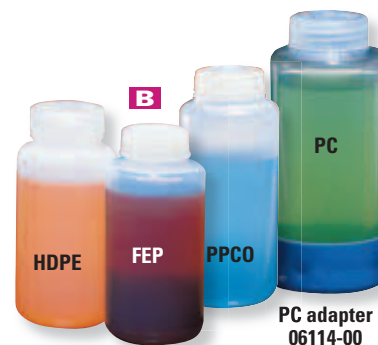
Feature molded-in graduations. Leakproof PP sealing caps are included. These conical-bottom bottles require adapter 06106-78 to fit most rotors; order adapter below.

PC adapter
06106-78

B 250- and 290-mL Bottles

Model 06107-20 is leakproof at low speeds—must be full, tightly capped, and used in a refrigerated centrifuge. Models 06107-00 and 06106-10 are leakproof at low speeds. Models 06106-12 and 06106-14 include a leakproof, wide-mouth sealing cap.

To use bottles with 38-mm closure at speeds of 10,000 x g or greater without leakage, or to spin hazardous materials, order 38-mm sealing cap assembly 06327-57 from page 185. Spherical-bottom bottle 06107-00 requires adapter 06114-00 to fit most rotors; order below.

PC adapter
06114-00

Key	Capacity (mL)	Material	Bottom profile	Dimensions (H x OD)	Max RCF (x g)	Closure included	Autoclavable	Adapter required	Catalog number	Qty/pk	Price/1 pk	Save 10% 6-29 pks	Save 15% 30-119 pks
A	175	PPCO	Conical	139.2 x 61.5 mm	27,500	58 mm, PP	Yes	06106-78	ED-06107-28	4			
		PC		140.0 x 61.4 mm					ED-06106-08				
B	250	PPCO	Flat	127.7 x 61.8 mm	13,200	38 mm, PP	Yes	17404-06†	ED-06105-20	4			
		HDPE		131.9 x 61.2 mm		43 mm, PP			ED-06107-10				
		FEP		128.8 x 60.0 mm		38 mm, Tefzel®			ED-06107-20				
	250	PC	Flat	127.6 x 61.8 mm	27,500	38 mm, PP	Yes	17404-06†	ED-06106-10	4			
Flat	135.1 x 61.5 mm	58 mm, PP	ED-06106-12										
Flat	133.4 x 60.7 mm	58 mm, PP	ED-06106-14										
Spherical	145.8 x 61.9 mm	38 mm, PP	ED-06107-00										

†These bottles require the noted adapter to fit the Sorvall GSA rotor; order adapters below.

Adapters for Centrifuge Bottles

Catalog number	Description	Material	Qty/pk	Price/1 pk	Save 10% 6-29 pks	Save 15% 30-119 pks	Save 20% 120+ pks
ED-06106-78	Adapter for 175-mL bottles 06107-28 and 06106-08; (adds 4.3 mm to bottle height)	PC	4				
ED-17404-06	Adapter for 250-mL bottles 06107-10 and -20; 06106-10, -12, and -14; and 06105-20	LDPE	6				
ED-06114-00	Adapter for 250-mL bottle 06107-00; (adds 5.8 mm to bottle height)	PC	4				