


**NALGENE®
Durable Burettes**

Individually calibrated to meet ASTM E 287 accuracy requirements

Use these clear, acrylic-body burettes with polymethylpentene tips and PTFE stopcocks over the entire pH range. Burettes are unaffected by dilute mineral acids and bases (except HF and ammonium hydroxide). The pH range of 1 to 14 is ideal and up to 5% wt/wt of acids or 30% bases can be used

Note: Not designed for use with alcohols or organic solvents.

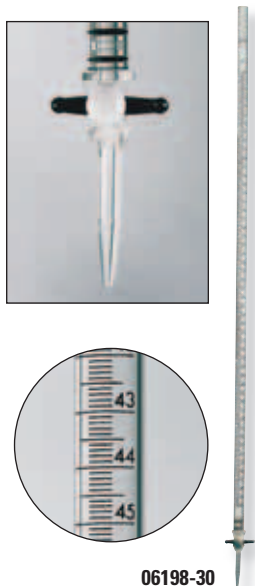

06198-30


Catalog number	Capacity	Graduation interval	Tolerance	Price
R-06198-20	25 mL	0.1 mL	±0.06 mL	
R-06198-30	50 mL	0.1 mL	±0.1 mL	
R-06198-40	100 mL	0.2 mL	±0.2 mL	

**PYREX® Brand
2103 Class A Burettes**

Colored scale, Class A, PTFE stopcock plug

- Capacity tolerance is calibrated in accordance with ASTM E 287

The burettes are calibrated in accordance with ASTM E 542. Tips are carefully drawn from accurate bore tubing to ensure proper drainage rates. Burettes have colored markings; fine, sharp lines; and large, easy-to-read numbers. The stopcock barrel has a smooth micro-finish to ensure leak-resistant performance. Each burette is supplied with a dust cover, and all sizes are furnished with a 2-mm bore stopcock plug.

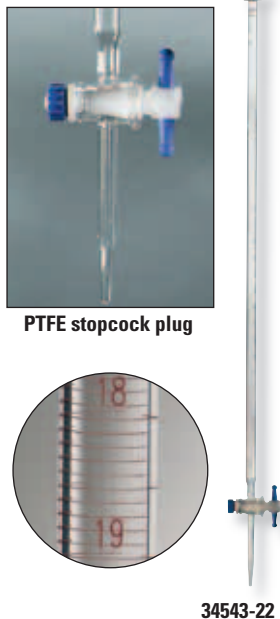

PTFE stopcock plug

34543-22

Catalog number	Capacity	Graduation interval	Tolerance	Price
R-34543-21	10 mL	0.05 mL	±0.02 mL	
R-34543-22	25 mL	0.10 mL	±0.03 mL	
R-34543-23	50 mL	0.10 mL	±0.05 mL	
R-34543-24	100 mL	0.20 mL	±0.10 mL	

**PYREX® Brand
2122 Burettes**

Features durable colored markings

Economical burettes are supplied with 2-mm straight-bore PTFE stopcock plugs. Ideal when accuracy of the Class A model is not critical. Microfinish of the barrel provides a precision fit. Tips are carefully drawn for accuracy to insure proper drainage rate. Dust cover included.



34544-50

Catalog number	Capacity	Graduation interval	Tolerance	Price
R-34544-50	10 mL	0.05 mL	±0.04 mL	
R-34544-52	25 mL	0.10 mL	±0.06 mL	
R-34544-54	50 mL	0.10 mL	±0.10 mL	
R-34544-56	100 mL	0.20 mL	±0.20 mL	

**PYREX® Brand 2116
Economy-Grade Burettes**

Replaceable components reduce cost

Burette components eliminate the need to purchase an entirely new burette if any part is damaged. Each burette has tooled top and bottom, white enamel graduations, and replaceable screw-thread locking PTFE stopcock. Replaceable tip end is ground to prevent tip from falling out.

34542-00

Catalog number	Capacity	Graduation interval	Tolerance	Qty/pk	Price/pk
R-34542-00	25 mL	0.10 mL	±0.06 mL	2	
R-34542-02	50 mL	0.10 mL	±0.10 mL	2	

- R-34542-04 Replacement body, 25 mL.
Case of 6 /cs
- R-34542-06 Replacement body, 50 mL.
Case of 6 /cs
- R-34542-08 Replacement tip. Case of 12 /cs
- R-34542-10 Replacement stopcock /ea

**PYREX® Brand 2094
Large-Volume Burettes**

Burettes are ideal for those requiring a larger capacity—up 1000 mL.

These dispensing burettes are equipped with a PTFE 2-mm bore stopcock plug to reduce freezing and lubricant contamination. Barrel has a microfinish for precision fit and the tips have the accuracy to provide required drainage rate. Each burette has a durable colored scale and dust cover.

34542-30

Catalog number	Capacity	Graduation interval	Tolerance	Price
R-34542-30	250 mL	1 mL	±2.0 mL	
R-34542-32	500 mL	5 mL	±2.5 mL	
R-34542-34	1000 mL	10 mL	±5.0 mL	