

**buy more,
save more**


6–29 packs save 10% 30–119 packs save 15% 120+ packs save 20%

Mix and match packs of any items from the “blue” tables to save!

Cable Ties, Tie Mounts, and Tensioning Tools

These cable ties are injection-molded and won't corrode or stretch. Durable locking mechanism holds securely even when used to bundle vibrating or flexing materials. Ties continue to hold tension even in oily spray or wet environments. Easily apply ties by hand or use a tensioning tool—order tools separately on page 230.

Ties are UL-component recognized, and are self-extinguishing as per UL 94 Flam. Class: V-2 (models 06830-85 and 06830-95 have a UL flame rating of UL94-HB). Ties withstand temperatures to 185°F (85°C), except for Barbed Design Cable Ties on page 230 (06830-50, -72, -72, -73, -74, and -75) that withstand temperatures to 167°F (75°C). All ties remain flexible to -40°F (-40°C). Efficient range of ties may be higher or lower in your specific application. Melting temperature is 495°F (257°C) for all cable ties except for Barbed Design Cable Ties (06830-50, -71, -72, -73, and -74) which have a melting point of 425°F (218°C).

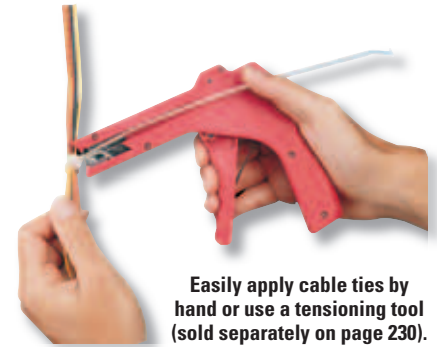


Easily apply cable ties by hand or use a tensioning tool (sold separately on page 230).

A Solid Design Cable Ties, NYL 6/6

Hold heavy loads; bent tip for easy installation.

Catalog number	Length	Bundle dia	Min loop strength	Spec met	Color	Qty/ pk	Price/ 1 pk	Save 10% 6–29 pks	Save 15% 30–119 pks	Save 20% 120+ pks
R-06830-52	4"	7/8"	18 lb	MS3367-4-9	White	1000				
R-06830-61	4"	7/8"	18 lb	MS3367-4-2	Red	1000				
R-06830-62	4"	7/8"	18 lb	MS3367-4-6	Blue	1000				
R-06830-63	4"	7/8"	18 lb	MS3367-4-5	Green	1000				
R-06830-64	4"	7/8"	18 lb	MS3367-4-4	Yellow	1000				
R-06830-65	4"	7/8"	18 lb	MS3367-4-3	Orange	1000				
R-06830-54	5 1/2"	1 1/4"	40 lb	MS3367-5-9	White	1000				
R-06830-56	7 1/2"	1 3/4"	50 lb	MS3367-1-9	White	1000				
R-06830-30	8"	2 1/8"	40 lb	—	White	1000				
R-06830-31	8"	2 1/8"	40 lb	—	Red	1000				
R-06830-32	8"	2 1/8"	40 lb	—	Blue	1000				
R-06830-33	8"	2 1/8"	40 lb	—	Green	1000				
R-06830-34	8"	2 1/8"	40 lb	—	Yellow	1000				
R-06830-41	8"	2 1/8"	40 lb	—	Orange	1000				
R-06830-36	14 1/2"	4"	120 lb	MS3367-3-9	White	50				
R-06830-58	15"	4"	50 lb	MS3367-2-9	White	100				
R-06830-37	21"	6"	120 lb	—	White	50				
R-06830-38	24"	7"	120 lb	—	White	50				
R-06830-39	28"	8"	120 lb	—	White	50				
R-06830-42	34"	10"	175 lb	—	White	50				

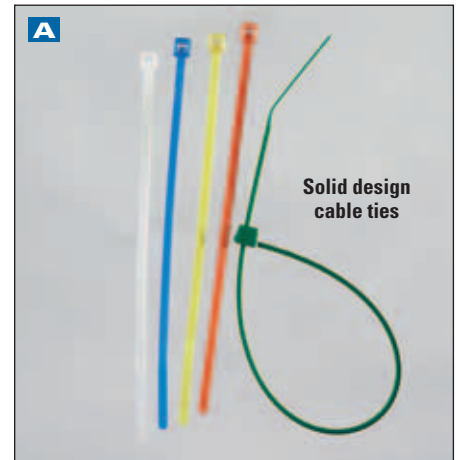

Solid design cable ties

B Solid Design Cable Ties with Identification Tab, NYL 6/6

Write on or mark the textured identification tab to easily identify your harnesses.

Catalog number	Length	Bundle dia	Min loop strength	Spec met	Color	Qty/ pk	Price/ 1 pk	Save 10% 6–29 pks	Save 15% 30–119 pks	Save 20% 120+ pks
R-06830-51	4"	7/8"	18 lb	MS3368-5-9E	White	1000				
R-06830-55	7 1/2"	1 1/4"	50 lb	MS3368-1-9A	White	1000				

B
06830-51



C Releasable Design Cable Ties, NYL 6/6

Reusable—work on a bundle without needing a new tie. Simply depress tab to remove tie.

Catalog number	Length	Bundle dia	Min loop strength	Spec met	Color	Qty/ pk	Price/ 1 pk	Save 10% 6–29 pks	Save 15% 30–119 pks	Save 20% 120+ pks
R-06830-57	7 1/2"	1 3/4"	50 lb	—	White	1000				
R-06830-26	11"	3"	50 lb	—	White	1000				




06830-57

D Ladder Design Cable Ties, NYL 6/6

Increased flexibility. Self-storing stub.

Catalog number	Length	Bundle dia	Min loop strength	Spec met	Color	Qty/ pk	Price/ 1 pk	Save 10% 6–29 pks	Save 15% 30–119 pks	Save 20% 120+ pks
R-06830-20	7"	1 3/4"	40 lb	—	White	1000				
R-06830-25	11"	3"	40 lb	—	White	1000				

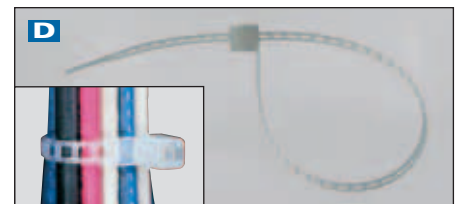

06830-25